

UC9600 Ultra High Density MTP®/MPO Module



- Available in Duplex LC and Quad LC
- Available in G657A, OM3 and OM4
- Utilises bend-insensitive fibre
- Plug & Play Installation
- Quick release mechanism
- Available configuration with 3x8F, 2x12F, 1x24F, splice
- Type "P" is Draka UC defacto, Type A and B are available.
- Pre-terminate and 100% test from factory
- Utilised with UC9600 1U/2U/4U Patch Panel
- Available in splice version with pigtail


Standards

ISO/IEC 11801, ANSI/TIA-568-C.3, RoHS Compliant


Specification

Item	Description	
Module Housing Material	ABS	
Module Housing Colour	Black	
Front Adaptor	Duplex or Quad LC with dust cap	
Rear Adaptor	MTP®/MPO with dust cap	
LC Adaptor Colours	OM3: AQUA; OM4: VIOLET; SM: BLUE	
Assemblies	Pre_installed male MTP®/MPO to fanout LC assemblies inside module	
Performance	Insert Loss (MTP®/MPO+LC) 1x8F/1x12F/1x24F	Return Loss(per fiber)
SM	0.75dB(standard) 0.50dB(Low Loss)	55dB
MM	0.5dB(standard) 0.35dB(Low Loss)	26dB
Installation temperature	0°C to +60°C	
Operating Temperature	-20°C to +70°C	
Storage & Shipping Temperature	-40°C to +75°C	

Construction

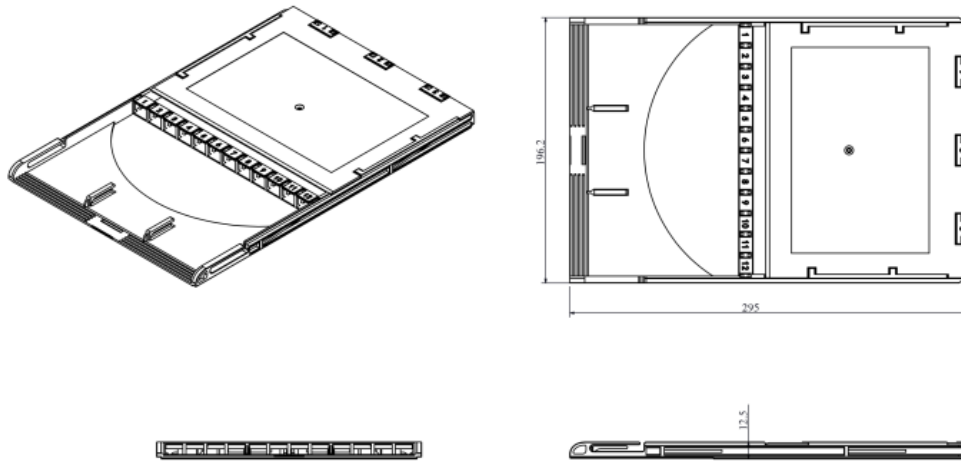

Ordering Information

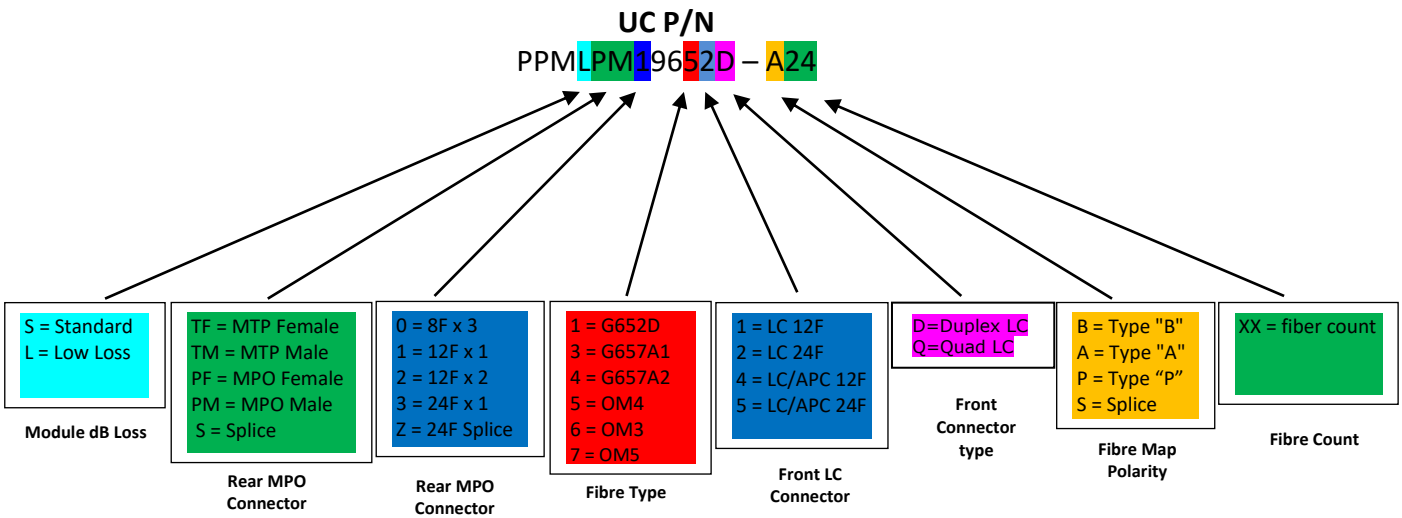

Remark: MPO/MTP-APC for SM, MPO/MTP-UPC for MM, LC-UPC as standard.

SAP1C	UC P/N	Material Description	Item per Packing Unit
		<u>Type "A"</u>	
	PPMLPM39652D – A24	UC9600 Series UHD Low Loss 1xMPO/UPC-24(M) to LC/UPC(D) Module MM OM4 Type A Violet	1
	PPMLPM29662D – A24	UC9600 Series UHD Low Loss 2xMPO/UPC-12(M) to LC/UPC(D) Module MM OM3 Type A Aqua	1
	PPMLPM09642D – A24	UC9600 Series UHD Low Loss 3xMPO/APC-8(M) to LC/UPC(D) Module SM G.657A2 Type A Blue	1
		<u>Type "B"</u>	
	PPMLPM39652D – B24	UC9600 Series UHD Low Loss 1xMPO/UPC-24(M) to LC/UPC(D) Module MM OM4 Type B Violet	1
	PPMLPM29662D – B24	UC9600 Series UHD Low Loss 2xMPO/UPC-12(M) to LC/UPC(D) Module MM OM3 Type B Aqua	1
	PPMLPM09642D – B24	UC9600 Series UHD Low Loss 3xMPO/APC-8(M) to LC/UPC(D) Module SM G.657A2 Type B Blue	1
		<u>Type "P"</u>	
	PPMLPM39652D – P24	UC9600 Series UHD Low Loss 1xMPO/UPC-24(M) to LC/UPC(D) Module MM OM4 Type P Violet	1
	PPMLPM29662D – P24	UC9600 Series UHD Low Loss 2xMPO/UPC-12(M) to LC/UPC(D) Module MM OM3 Type P Aqua	1
	PPMLPM09642D – P24	UC9600 Series UHD Low Loss 3xMPO/APC-8(M) to LC/UPC(D) Module SM G.657A2 Type P Blue	1
		<u>Splice</u>	
	PPMSSZ9652D – S24	UC9600 Series UHD Standard Splice LC/UPC 24F MM OM4 Violet with pigtail	1

Enquiries

Please contact our local sales office or mms.asia@prysmiangroup.com

Multimedia Solutions is the data communication portfolio of Prysmian Group and comprises all the necessary portfolio of cable solutions for data communication.

Ask about UCCONNECT® for a complete Structured Cabling Solution with 25 Years System Warranty.

Visit www.DrakaUC.com for more information.

PrysmianGroup 2020, All Rights Reserved

All sizes and values without tolerances are reference values. Specifications are for product as supplied by PrysmianGroup: any modification or alteration afterwards of product may give different result.

The information contained within this document must not be copied, reprinted or reproduced in any form, either wholly or in part, without the written consent of PrysmianGroup. The information is believed to be correct at the time of issue. PrysmianGroup reserves the right to amend this specification without prior notice. This specification is not contractually valid unless specifically authorized by PrysmianGroup.